


**HWQFN24: plastic thermal enhanced very very thin quad flat package; no leads;**  
**24 terminals; body 4 x 4 x 0.75 mm**

SOT994-1

 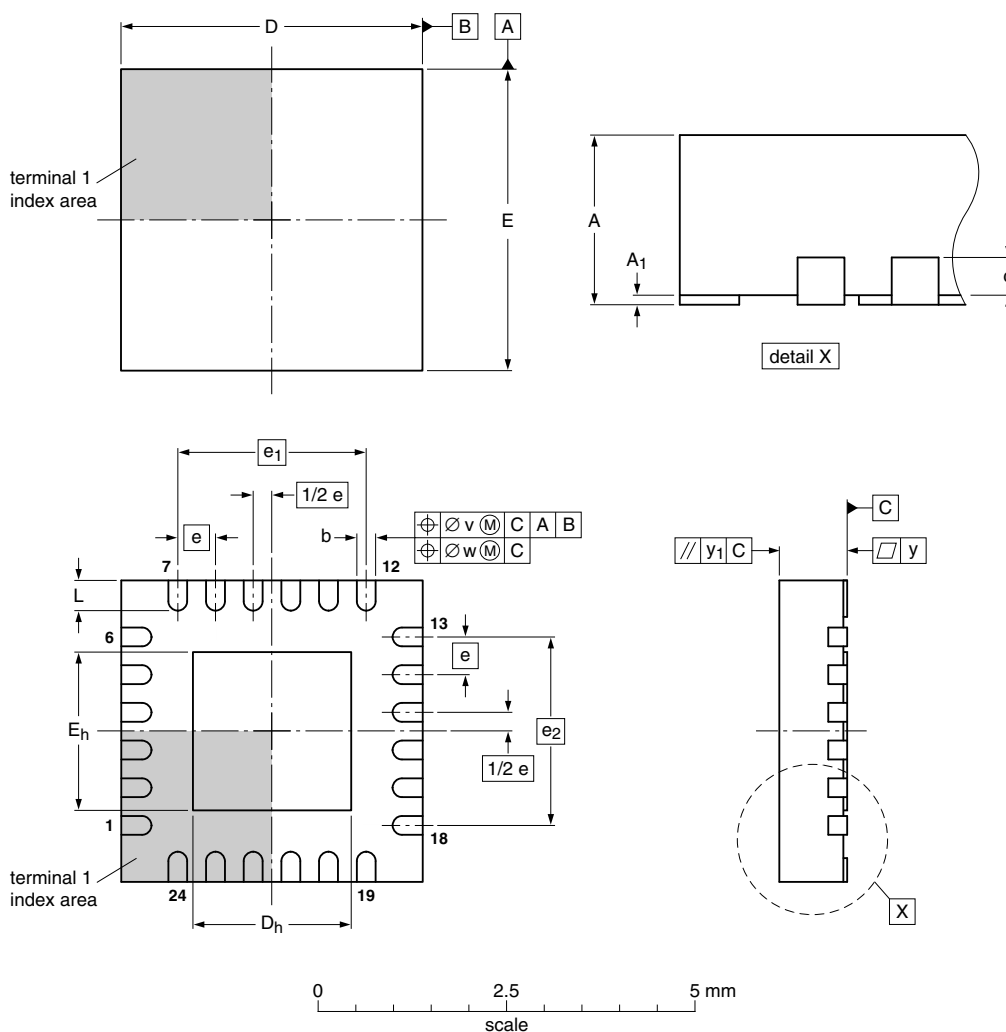


**DIMENSIONS (mm are the original dimensions)**

UNIT	$A^{(1)}$ max	$A_1$	$b$	$c$	$D^{(1)}$	$D_h$	$E^{(1)}$	$E_h$	$e$	$e_1$	$e_2$	$L$	$v$	$w$	$y$	$y_1$
mm	0.8	0.05 0.00	0.30 0.18	0.2	4.1 3.9	2.25 1.95	4.1 3.9	2.25 1.95	0.5	2.5	2.5	0.5 0.3	0.1	0.05	0.05	0.1

**Note**

1. Plastic or metal protrusions of 0.075 mm maximum per side are not included.

OUTLINE VERSION	REFERENCES				EUROPEAN PROJECTION	ISSUE DATE
	IEC	JEDEC	JEITA			
SOT994-1	---	MO-220	---			07-02-07- 07-03-03