 



## Plastic single-ended surface-mounted package (LFPAK); 4 leads

SOT1023

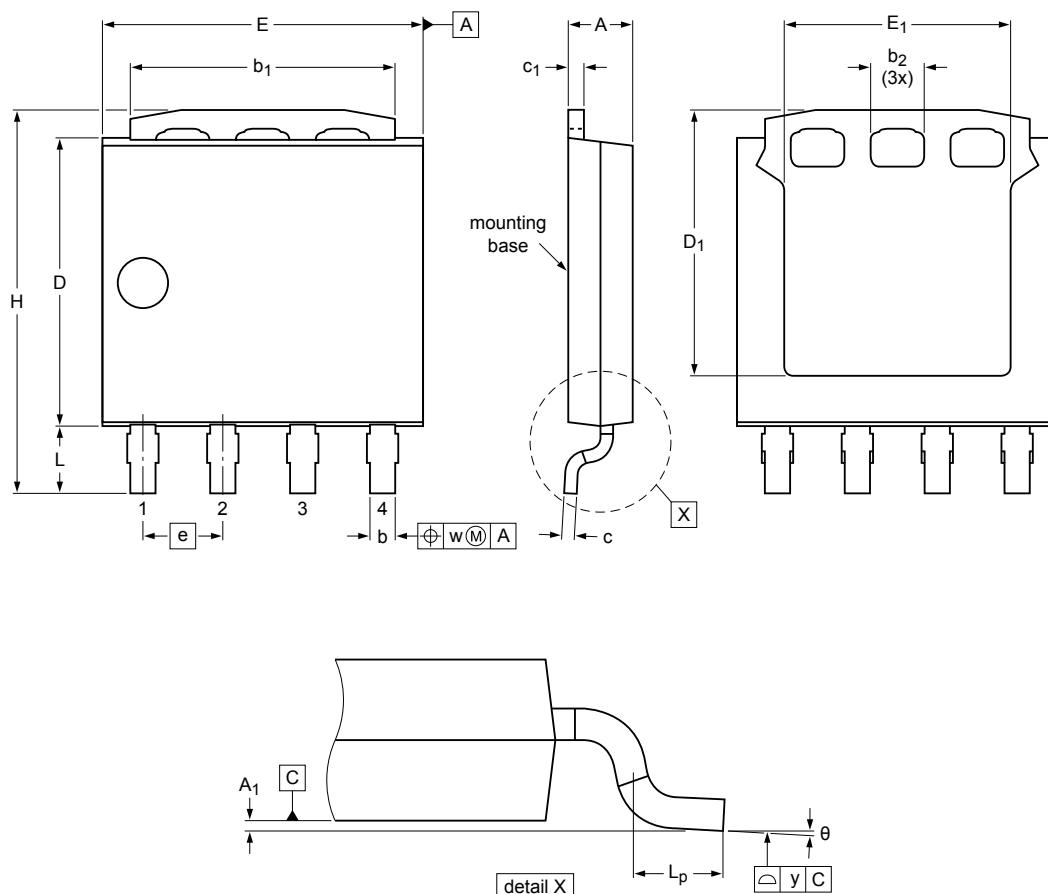

### Dimensions

Unit	A	A <sub>1</sub>	b	b <sub>1</sub>	b <sub>2</sub>	c	c <sub>1</sub>	D <sup>(1)</sup>	D <sub>1</sub> <sup>(1)</sup>	E <sup>(1)</sup>	E <sub>1</sub> <sup>(1)</sup>	e	H	L	L <sub>p</sub>	w	y	θ
max	1.10	0.15	0.50	4.41		0.25	0.30	4.70	4.45	5.30	3.7		6.2	1.3	0.85			8°
nom					0.85							1.27				0.25	0.1	
min	0.95	0.00	0.35	3.62		0.19	0.24	4.45		4.95	3.5		5.9	0.8	0.40			0°

### Note

1. Plastic or metal protrusions of 0.15 mm per side are not included.

sot1023\_po

Outline version	References			European projection	Issue date
	IEC	JEDEC	JEITA		
SOT1023					09-05-26 11-12-09