




# **750 W CW over 700-1300 MHz, 50 V RF Power LDMOS Transistor**

## **MRF13750H**

Last Updated: Feb 15, 2024

These 750 W CW transistors, MRF13750H and MRF13750HS, are designed for industrial, scientific and medical (ISM) applications in the 700 to 1300 MHz frequency range. The transistors are capable of CW or pulse power in narrowband operation.

## MRF13750H 915 MHz Reference Circuit Block Diagram

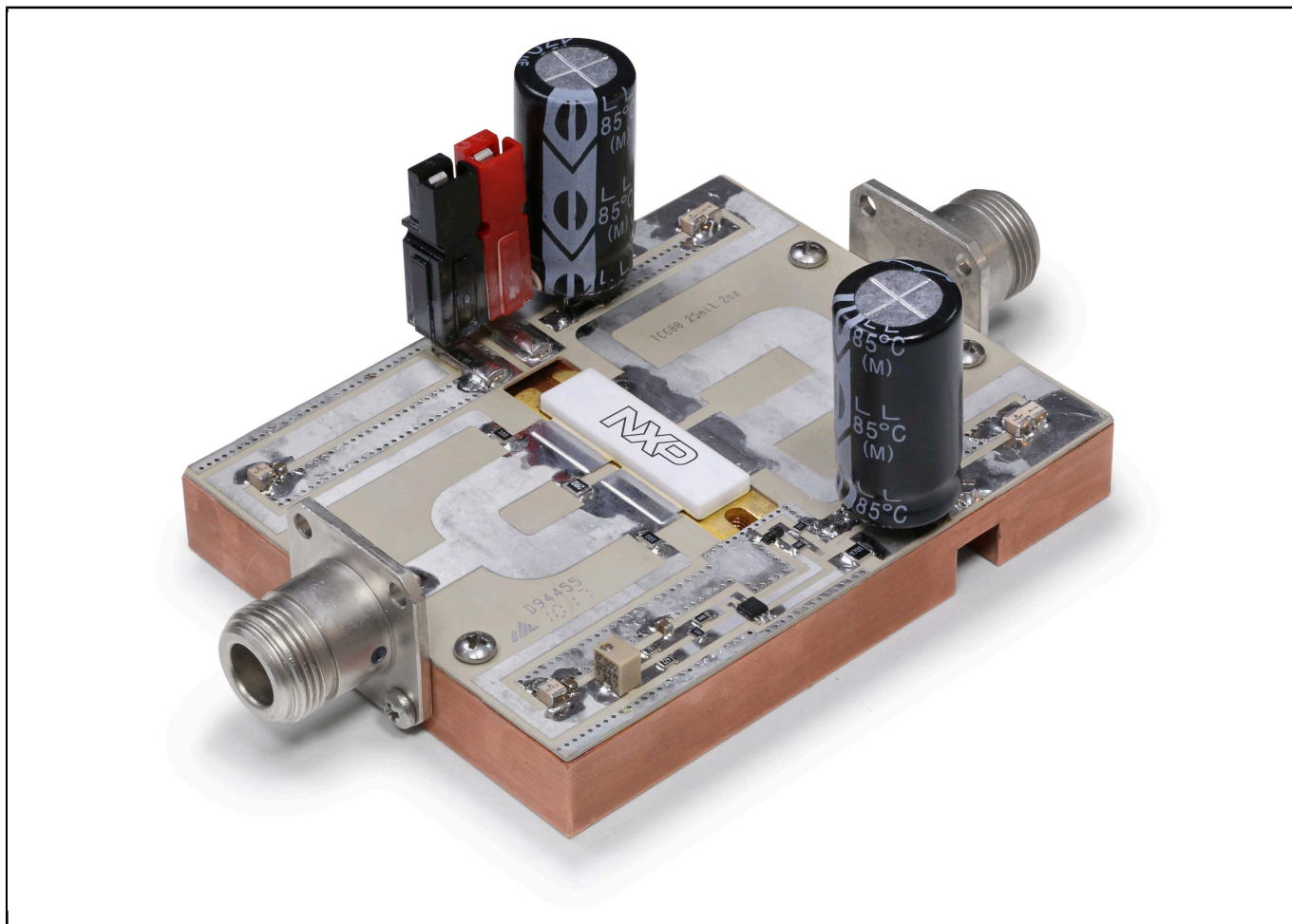

View additional information for [750 W CW over 700-1300 MHz, 50 V RF Power LDMOS Transistor](#).

**Note:** The information on this document is subject to change without notice.

**[www.nxp.com](http://www.nxp.com)**

NXP and the NXP logo are trademarks of NXP B.V. All other product or service names are the property of their respective owners. The related technology may be protected by any or all of patents, copyrights, designs and trade secrets. All rights reserved. © 2024 NXP B.V.